



## 60" Industrial Fan - HF1160


- HF1160BS** - Brushed Steel Housing & Brushed Steel Blades
- HF1160WW** - Appliance White Housing & Appliance White Blades
- HF1160BQ** - Barbeque Black Housing & Barbeque Black Blades

- 60" span high-efficiency airfoil blades
- Blades must be mounted at least 10 feet above the floor
- Single speed fan using 120 volts
- Fan hung at 20 feet covers 3,500 sq. ft.
- Fan hung at 30 feet covers 2,900 sq. ft.
- Fan hung at 40 feet covers 2,200 sq. ft.
- Not reversible
- 6" downrod included
- Three Airfoil Blades
- Ships to Canada
- SW 81 or SW82 Control Sold Separately
- Not for residential applications



### 60" Industrial Fan Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
11562	118	90

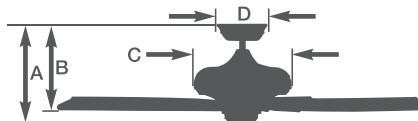

A: 12.8" B: 12.8" C: 7.5" D: 5.2"

go **ABOVE**<sup>™</sup>