



Veloce™ - CF230

CF230BS - Brushed Steel Housing, Brushed Steel/Chocolate Blades

- 46" blade span
- Integrated light fixture uses one 50-watt GU10 base MR16 halogen bulb *(included)*
- Dual mounting for close-to-the-ceiling or downrod installation
- 4.5" downrod included
- Four reversible blades
- Dual-mount feature
- Ships to Canada
- Accessory No-Light Plate sold separately (CP230xxx)



LIMITED LIFETIME
MOTOR WARRANTY



DAMP
LOCATION




SHIPS TO
CANADA
FAN ONLY



SR400 Remote Included

Veloce™ Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
5250	52	102

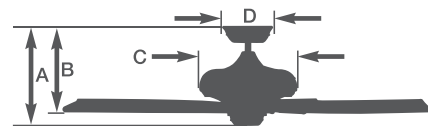

A: 14.4"/11.1 B: 11.9" C: 7.5" D: 5.0"

go **ABOVE™**

Specifications subject to change without notice.