



No-Light Option



Medium-base light fixture with three 13-watt CFL bulbs *(included)*

Ashland - CF717

CF717ORB - Oil Rubbed Bronze with Reversible Dark Cherry/Walnut Blades

CF717BS - Brushed Steel with Reversible Dark Cherry/Walnut Blades

CF717SW - Satin White with Reversible Satin White/Maple Blades


- No-Light Option included
- Medium-base light fixture with three 13-watt CFL bulbs *(included)*
- 52" blade span
- 80" lead wires
- 4.5" downrod included

Motor: 153x17mm



Ashland Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
4939	56	88

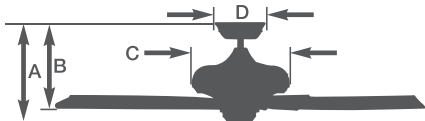

A: 17/13" B: 9.5/13.5" C: 12" D: 5.3"

Included:




FIVE REVERSIBLE BLADES



DUAL-MOUNT FEATURE



LIGHT FIXTURE

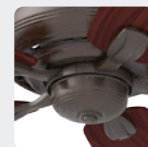

NO-LIGHT SWITCH CUP