



Penbrooke Select - CF5100


- CF5100BS** - Brushed Steel Housing
- CF5100GES** - Golden Espresso Housing
- CF5100ORB** - Oil Rubbed Bronze Housing
- CF5100SW** - Satin White Housing
- CF5100VNB** - Venetian Bronze Housing
- CF5100VS** - Vintage Steel Housing

- Blade Select Series (Blades Sold Separately)
- 44", 54" & 60" blade span
- 4.5" downrod included
- Light fixture adaptable & AL100 adaptable
- Ships to Canada (for Spring availability)



Penbrooke Select Energy Ratings at High Speed

| | | |
|------------------------------|---|--|
| Airflow Cubic Ft Per Min. | Electricity Use Watts (Excl. Lights) | Airflow Efficiency Cubic Ft Per Min. Per Watt |
| 6222 | 98 | 63 |

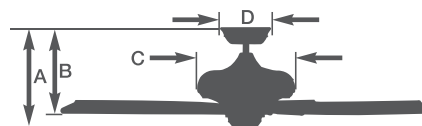

A: 13.0" B: 12.0" C: 13.0" D: 6.7"

go **ABOVE**[™]

Specifications subject to change without notice.