



50" Pro Series II™ - CF711


- CF711ORS** - Oil Rubbed Bronze Housing, Dark Cherry/Medium Oak Blades, Amber Scavo Glass
- CF711BS** - Brushed Steel Housing, Dark Cherry/Mahogany Blades, Opal Matte Glass
- CF711ORB** - Oil Rubbed Bronzed Housing, Dark Cherry/Medium Oak Blades, Opal Matte Glass
- CF711AB** - Antique Brass Housing, Walnut/Medium Oak Blades, Opal Matte Glass
- CF711WW** - Appliance White Housing, Appliance White/Bleached Oak Blades, Opal Matte Glass

- 50" blade span
- Snap-on glass for easy installation
- Light fixture furnished with four 13-watt medium base compact fluorescent bulbs *(included)*
- UL rated for four 60-watt incandescent
- Precision-Lock™ blade arms with pre-attached screws allow for quick and easy assembly of blades
- Removable light fixture can be replaced with switch cover if desired *(included)*
- Easy install mounting bracket
- Dual mounting for close-to-the-ceiling or downrod installation
- 4.5" downrod included
- Five Reversible Blades



50" Pro Series II™ Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
5403	84	64

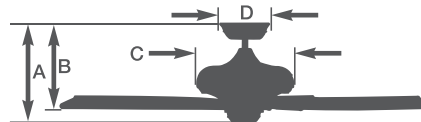

A: 14.8"/18.5" B: 8.3"/11.5" C: 11.5" D: 5.2"

go **ABOVE**™