



Style Category:
Contemporary
Motor: 153x18mm
Blade Pitch: 12°
RPM Range: 130-280
High Speed Amps: 0.5
Accepts 2.5" Downrod:
Yes
Wet/Damp: Wet*
Control Included:
6-Speed Remote Control
Receiver Included:
RC188
Remote Reverse Switch
Dimming Light: Yes
AL100 Adaptable: No

44" Curva™ - CF244

NEW FINISH ADDITION - GRAPHITE

CF244GRT - Graphite with Weather-Resistant Graphite Blades, Opal Matte Glass

- DEALER PRICE: \$160.56 | IMAP: \$289.00

CF244BS - Brushed Steel with Weather-Resistant Brushed Steel Blades, Opal Matte Glass

- DEALER PRICE: \$160.56 | IMAP: \$289.00

CF244ORB - Oil Rubbed Bronze with Weather-Resistant Oil Rubbed Bronze Blades, Opal Matte Glass

- DEALER PRICE: \$160.56 | IMAP: \$289.00

CF244WW - Appliance White with Weather-Resistant Appliance White Blades, Opal Matte Glass

- DEALER PRICE: \$149.44 | IMAP: \$269.00


- 44" Blade Span
- Integrated Light Fixture Uses Two 50-watt Mini-Candelabra Halogen Bulbs (included)
- 4.5" Downrod Included
- Three Weather-Resistant Blades
- Removable No-Light Plate Included
- 6-Speed L.E.D. Remote Control Included
- Wet Location (*Brushed Steel Not Recommended for Outdoor use)
- Ships to Canada
- Also Available in 52" Span as CF252



*Brushed Steel not recommended for outdoor use

44" Curva™ Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
4280	44	97

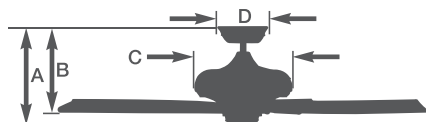

A: 14.9" B: 12.0" C: 9.6" D: 6.5"

Included:



THREE WEATHER-RESISTANT BLADES



REMOVABLE NO-LIGHT PLATE



INTEGRATED LIGHT FIXTURE



6-Speed Remote Control with Receiver*

*Controls are recommended for indoor use only.