



## Midway Eco™ - CF955

- CF955BS** - Brushed Steel Housing, Midnight Bordeaux Blades, Opal Matte Glass
- CF955WW** - Appliance White Housing, Appliance White Blades, Opal Matte Glass
- CF955ORB** - Oil Rubbed Bronze Housing, Oil Rubbed Bronze Blades, Opal Matte


- 54" airfoil design blade
- Integrated light fixture uses four 13-watt GU24 fluorescent bulbs *(included)*
- 4.5" downrod included
- Five Custom Blades
- 6-speed LED remote control with built-in receiver included
- EcoMotor
- Energy Star Rated
- Ships to Canada



Remote Control with  
Built-in Receiver

### Midway Eco™ Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
6085	18	336

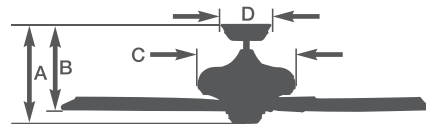

A: 16.5" B: 11.5" C: 12.3" D: 6.5"

go **ABOVE**™