



## Pro Series ES - CF713


- CF713BS** - Brushed Steel Housing, Dark Cherry/Mahogany Blades, Alabaster Swirl Glass
- CF713ORB** - Oil Rubbed Bronze Housing, Dark Cherry/Medium Oak Blades, Amber Scavo Glass
- CF713WW** - Appliance White Housing, Appliance White/Bleached Oak Blades, Alabaster Swirl Glass

- 50" blade span
- Light fixture uses three 13-watt GU-24 bulbs *(included)*
- Precision-Lock™ blade arms with pre-attached screws allow for quick and easy assembly of blades
- Removable light fixture can be replaced with switch cover if desired *(included)*
- Easy install mounting bracket
- Dual mounting for close-to-the-ceiling or downrod installation
- 4.5" downrod included
- Removable No-Light Plate included
- Five Reversible Blades
- Energy Star Rated
- Ships to Canada



### Pro Series ES Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
5027	65	77

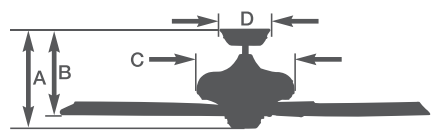

A: 18.5"/14.8"    B: 8.3"/11.5"    C: 11.5"    D: 5.3"

go **ABOVE**™