



Volta - CF590

CF590BQ - Barbecue Black with Natural Cherry Blades (shown)

CF590PT - Platinum with Platinum Blades

CF590SW - Satin White with Satin White Blades

- 54" blade span **Motor:** 172x20mm
- Integrated L.E.D. light kit
 - 2,600 Lumens
 - 95 CRI
 - 3,000K CCT
 - 32 Watts
- 4.5" downrod included
- Optional no-light plate included

WET LOCATION RATED

SHIPS TO CANADA

INTEGRATED L.E.D. LIGHTING

LIMITED LIFETIME MOTOR WARRANTY

Included:



THREE CUSTOM BLADES



SR401
Remote Control



INTEGRATED L.E.D. LIGHT FIXTURE




REMOVABLE NO-LIGHT PLATE

Volta Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
6300*	81.5*	77.3*

*Estimated. Visit our website at emersonfans.com for up-to-date information.

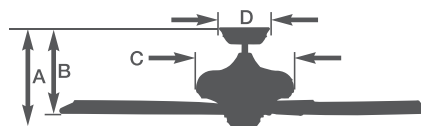

A: 14.5" B: 13.2" C: 8.7" D: 5.8"

go ABOVE

Specifications subject to change without notice.