



Style Category:
Contemporary

Motor: 153x18mm

Blade Pitch: 12°

RPM Range: 130-280

High Speed Amps: 0.5

Accepts 2.5" Downrod:
No

Wet/Damp: Wet*

Control Included:
6-Speed Remote Control

Receiver Included:
RC188

Remote Reverse Switch

Dimming Light: Yes

AL100 Adaptable: No

44" Curva Sky™ - CF144

NEW FINISH ADDITION - GRAPHITE

CF144GRT - Graphite with Weather-Resistant Graphite Blades, Opal Matte Glass
- **DEALER PRICE: \$160.56 | IMAP: \$289.00**

CF144BS - Brushed Steel, Weather-Resistant Brushed Steel Blades, Opal Matte Glass
- **DEALER PRICE: \$160.56 | IMAP: \$289.00**

CF144ORB - Oil Rubbed Bronze, Weather-Resistant Appliance Blades, Opal Matte Glass
- **DEALER PRICE: \$160.56 | IMAP: \$289.00**

CF144WW - Appliance White, Weather-Resistant Appliance White Blades, Opal Matte Glass
- **DEALER PRICE: \$149.44 | IMAP: \$269.00**


- 44" Blade Span
- Integrated Light Fixture Uses Two 50-Watt Mini-Candelabra Halogen Bulbs (Included)
- Three Weather-Resistant Blades
- Removable No-Light Plate Included
- 6-Speed L.E.D. Remote Control
- Wet Location (*Brushed Steel Not Recommended for Outdoor Use)
- Ships to Canada
- Also Available in 52" Span as CF152



*Brushed Steel not recommended for outdoor use

44" Curva Sky™ Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
4217	45	93

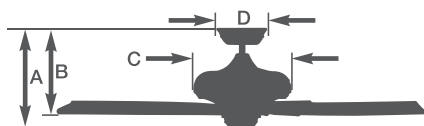

A: 12.6" B: 12.0" C: 9.6" D: 6.5"

Included:




**THREE
WEATHER-
RESISTANT
BLADES**



**REMOVABLE
NO-LIGHT
PLATE**

*Controls are recommended for indoor use only.

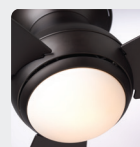

**INTEGRATED
LIGHT
FIXTURE**



**6-Speed
Remote Control
with Receiver***

*Controls are recommended for indoor use only.