



Style Category:
Pro Series

Motor: 153x17mm

Blade Pitch: 11.5°

RPM Range: 70-170

High Speed Amps: 0.47

Accepts 2.5" Downrod:
No

Wet/Damp: Indoor

Control Included:
Pull Chain

Receiver Included:
N/A

Manual Reverse Switch

Dimming Light: Yes

AL100 Adaptable: No

Ashland - CF717

NEW FINISH ADDITION

CF717AP - Antique Pewter with Charcoal/Timber Gray Blades *NEW BLADE FINISH*
- **BASE DEALER PRICE: \$105.00 | IMAP: \$189.00**

CF717ORB - Oil Rubbed Bronze with Reversible Dark Cherry/Walnut Blades
- **BASE DEALER PRICE: \$105.00 | IMAP: \$189.00**

CF717BS - Brushed Steel with Reversible Dark Cherry/Walnut Blades - **BASE DEALER PRICE: \$105.00 | IMAP: \$189.00**


CF717SW - Satin White with Reversible Satin White/Maple Blades - **Base Dealer Price: \$99.44 | IMAP: \$179.00**

- No-Light Option Included
- Medium-Base Light Fixture with Three 13-Watt CFL Bulbs *(Included)*
- 52" Blade Span
- 4.5" Downrod Included
- Dual Mounting for Close-to-the-Ceiling or Downrod Installation



Ashland Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
4939	56	88

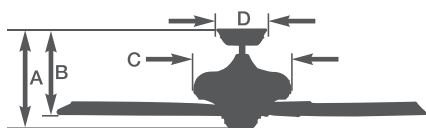

A: 17/13" B: 9.5/13.5" C: 12" D: 5.3"

Included:



FIVE REVERSIBLE BLADES



DUAL-MOUNT FEATURE



LIGHT FIXTURE



NO-LIGHT SWITCH CUP