



Pro Series™ - CF712


- CF712ORB** - Oil Rubbed Bronze Housing, Dark Cherry/Medium Oak Blades, Amber Scavo Glass
- CF712WW** - Appliance White Housing, Appliance White/Bleached Oak Blades, Opal Matte Glass
- CF712BS** - Brushed Steel Housing, Mahogany/Dark Cherry Blades, Opal Matte Glass
- CF712AW** - Summer White Housing, Summer White/Bleached Oak Blades, Opal Matte Glass
- CF712AB** - Antique Brass Housing, Medium Oak/Walnut Blades, Opal Matte Glass
- CF712WORB** - Oil Rubbed Bronze Housing, Dark Cherry/Medium Oak Blades, Opal Matte Glass

- 50" blade span
- Light fixture uses three 60-watt candelabra basebulbs *(included)*
- Precision-Lock™ blade arms with pre-attached screws allow for quick and easy assembly of blades
- Removable light fixture can be replaced with switch cover if desired *(included)*
- Easy install mounting bracket
- Dual mounting for close-to-the-ceiling or downrod installation
- 4.5" downrod included
- Removable No-Light Plate
- Five Reversible Blades
- Ships to Canada



Pro Series™ Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
5224	61	85

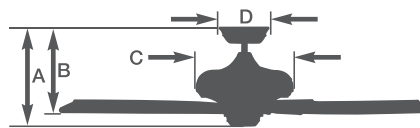

A: 18.5"/14.8" B: 8.3"/11.5" C: 11.5" D: 5.2"

go **ABOVE**™