



Style Category:
Contemporary

Motor: 153x22mm

Blade Pitch: 14°

RPM Range: 59-189

High Speed Amps: 0.55

Accepts 2.5" Downrod:
Yes

Wet/Damp: Indoor

Control Included:
4-Speed Remote

Receiver Included:
RCFP

Manual Reverse Switch

Dimming Light: Yes

AL100 Adaptable: No

Highpointe™ - CF205

NEW FINISH ADDITION - GRAPHITE

CF205GRT - Graphite with Charcoal/Timber Gray Blades, Opal Matte Glass - **DEALER PRICE: \$200.56 | IMAP: \$361.00**

CF205BS - Brushed Steel with Dark Mahogany Blades, Opal Matte Glass - **DEALER PRICE: \$200.56 | IMAP: \$361.00**

CF205GES - Golden Espresso with Chocolate Blades, Sandstone Glass - **DEALER PRICE: \$200.56 | IMAP: \$361.00**


CF205VS - Vintage Steel with Honey Oak/Riverwash Blades, Vintage Cream Glass
- **DEALER PRICE: \$200.56 | IMAP: \$361.00**

- 54" Blade Span
- Integrated Light Fixture Uses Two 50-watt Mini-Candelabra Halogen Bulbs (included)
- 6" and 12" Downrod Included
- Three Custom Blades
- Integrated Light Fixture
- Removable No-Light Plate Included
- Removable Decorative Cables Included
- 4-Speed Remote Control with Receiver Included
- Ships to Canada



Highpointe™ Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
5678	66	86

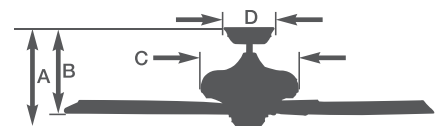

A: 16.5"/22.5" B: 15.0"/21.0" C: 8.0" D: 6.3"

Included:



THREE
CUSTOM
BLADES



REMOVABLE
DECORATIVE
CABLES

For use on 9"
ceilings or higher



INTEGRATED
LIGHT
FIXTURE



REMOVABLE
NO-LIGHT
PLATE



4-Speed
Remote Control
with Receiver

go **ABOVE**®

Specifications subject to change without notice.