



## 4th Avenue - CF766

- CF766BS**   ▪ Brushed Steel Housing, Chocolate Blades, Opal Matte Glass
- CF766ORB**   ▪ Oil Rubbed Bronze Housing, Oil Rubbed Bronze Blades, Opal Matte Glass
- CF766SBS**   ▪ Brushed Steel Housing, Brushed Steel Blades, Opal Matte Glass
- CF766SW**   ▪ Satin White Housing, Satin White Blades, Opal Matte Glass
- CF766VS**   ▪ Vintage Steel Housing, Riverwash Blades, Vintage Cream Glass


- 60" blade span
- Integrated light fixture uses two 60-watt candelabra bulbs (*included*)
- 8" downrod included
- Three Plywood Blades
- Ships to Canada



SW405  
Remote Control  
with Receiver

### 4th Avenue Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
6403	48	132

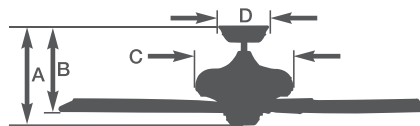

A: 17.9"    B: 9.4"    C: 8.7"    D: 6.4"

go **ABOVE**™