



Style Category: Contemporary
 Motor: 153x18mm
 Blade Pitch: 12°
 RPM Range: 75-195
 High Speed Amps: 0.5
 Accepts 2.5" Downrod: Yes
 Wet/Damp: Wet*
 Control Included: 6-Speed Remote Control
 Receiver Included: RC188
 Remote Reverse Switch
 Dimming Light: Yes
 AL100 Adaptable: No

52" Curva™ - CF252

NEW FINISH ADDITION - GRAPHITE

CF252GRT - Graphite with Weather-Resistant Graphite Blades, Opal Matte Glass
 - DEALER PRICE: \$166.11 | IMAP: \$299.00

CF252BS - Brushed Steel Housing, Weather-Resistant Brushed Steel Blades, Opal Matte Glass
 - DEALER PRICE: \$166.11 | IMAP: \$299.00

CF252ORB - Oil Rubbed Bronze Housing, Weather-Resistant Oil Rubbed Bronze Blades, Opal Matte Glass
 - DEALER PRICE: \$166.11 | IMAP: \$299.00

CF252WW - Appliance White Housing, Weather-Resistant Oil Rubbed Bronze Blades, Opal Matte Glass
 - DEALER PRICE: \$155.00 | IMAP: \$279.00


- 52" Blade Span
- Integrated Light Fixture Uses Two 50-watt Mini-Candelabra Halogen Bulbs (included)
- 4.5" Downrod Included
- Three Weather-Resistant Blades
- Removable No-Light Plate Included
- 6-Speed L.E.D. Remote Control Included
- Wet Location (*Brushed Steel Not Recommended for Outdoor Use)
- Ships to Canada
- Also Available in 44" Span as CF244



*Brushed Steel not recommended for outdoor use

52" Curva™ Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
5329	45	118

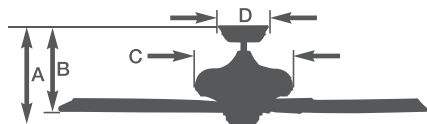

A: 14.9" B: 12.0" C: 9.6" D: 6.5"

Included:



THREE WEATHER-RESISTANT BLADES



REMOVABLE NO-LIGHT PLATE



INTEGRATED LIGHT FIXTURE



6-Speed Remote Control with Receiver*

*Controls are recommended for indoor use only.