



Style Category:  
Indoor/Outdoor  
Motor: 188x15mm  
Blade Pitch: 12°  
RPM Range: 65-160  
High Speed Amps: 0.53  
Accepts 2.5" Downrod:  
No  
Wet/Damp: Wet  
Control Included:  
Pull Chain  
Receiver Included:  
N/A  
Manual Reverse Switch  
Dimming Light: N/A  
AL100 Adaptable: No


**NEW!**


## Kailua Cove - CF380


**CF380VNB** - Venetian Bronze with Weather-Resistant Medium Antique Brown Blades - **Dealer Price: \$166.11 | IMAP: \$299.00**


**CF380SW** - Satin White with Weather-Resistant Driftwood Blades - **Dealer Price: \$155.00 | IMAP: \$279.00**

- 52" Blade Span
- Wet Location Rated
- Five Weather-Resistant Blades
- Light Fixture Adaptable
- 4.5" Downrod Included

 **WET LOCATION RATED**


 **LIMITED LIFETIME MOTOR WARRANTY**

 **SHIPS TO CANADA**

 **L.E.D. LIGHT FIXTURE ADAPTABLE**

### Kailua Cove Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
5127	63.6	81

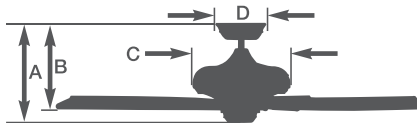

A: 13.3" B: 11.4" C: 11.3" D: 7.2"

**go ABOVE®**

Specifications subject to change without notice.