



44" Curva™ - CF244

- CF244BS** - Brushed Steel Housing, Weather-Resistant Brushed Steel Blades, Opal Matte Glass
- CF244ORB** - Oil Rubbed Bronze Housing, Weather-Resistant Oil Rubbed Bronze Blades, Opal Matte Glass
- CF244WW** - Appliance White Housing, Weather-Resistant Appliance White Blades, Opal Matte Glass


- 44" blade span
- Integrated light fixture uses two 50-watt mini-candelabra halogen bulbs *(included)*
- 4.5" downrod included
- Three Weather-Resistant Blades
- Removable No-Light Plate Included
- 6-Speed LED Remote Control Included
- Wet Location (In ORB and WW Finishes Only)
- Ships to Canada
- Also Available in 52" Span as CF252



Remote Control with Receiver

44" Curva™ Energy Ratings at High Speed

| | | |
|------------------------------|-----------------------------------------|--------------------------------------------------|
| Airflow Cubic Ft Per Min. | Electricity Use Watts (Excl. Lights) | Airflow Efficiency Cubic Ft Per Min. Per Watt |
| 4280 | 44 | 97 |

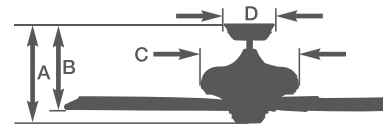

A: 14.9" B: 12.0" C: 9.6" D: 6.5"

go **ABOVE**™