



## 52" Curva™ - CF252

- CF252BS** - Brushed Steel Housing, Weather-Resistant Brushed Steel Blades, Opal Matte Glass
- CF252ORB** - Oil Rubbed Bronze Housing, Weather-Resistant Oil Rubbed Bronze Blades, Opal Matte Glass
- CF252WW** - Appliance White Housing, Weather-Resistant Oil Rubbed Bronze Blades, Opal Matte Glass


- 52" blade span
- Integrated light fixture uses two 50-watt mini-candelabra halogen bulbs *(included)*
- 4.5" downrod included
- Three Weather-Resistant Blades
- Removable No-Light Plate Included
- 6-Speed LED Remote Control Included
- Wet Location (In ORB and WW Finishes Only)
- Ships to Canada
- Also Available in 44" Span as CF244



Remote Control with Receiver

### 52" Curva™ Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
5329	45	118

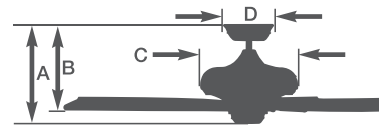

A: 14.9" B: 12.0" C: 9.6" D: 6.5"

go **ABOVE**™