



## 52" Curva Sky™ - CF152

- CF152BS** - Brushed Steel Housing, Weather-Resistant Brushed Steel Blades, Opal Matte Glass
- CF152WW** - Appliance White Housing, Weather-Resistant Appliance White Blades, Opal Matte Glass
- CF152ORB** - Oil Rubbed Bronze Housing, Weather-Resistant Oil Rubbed Bronze Blades, Opal Matte Glass


- 52" blade span
- Integrated light fixture uses two 50-watt mini-candelabra halogen bulbs *(included)*
- Three Weather-Resistant Blades
- Removable No-Light Plate Included
- 6-Speed LED Remote Control
- Wet Location (in WW and ORB Finishes Only)
- Ships to Canada
- Also Available in 44" Span as CF144



Remote Control with Receiver

52" Curva Sky™ Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
5393	46	116

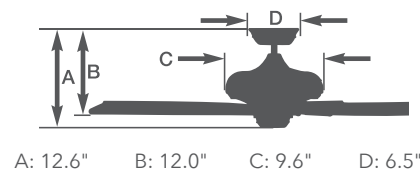

go **ABOVE**™