



Amhurst - CF880

- CF880BS** - Brushed Steel Housing, Dark Cherry/Chocolate Blades, Opal Matte Glass
- CF880VNB** - Venetian Bronze Housing, Dark Cherry/Honey Oak Blades, Cream Bubble Glass
- CF880VS** - Vintage Steel Housing, Riverwash/Walnut Blades, Cream Bubble Glass


- 54" blade span
- Integrated light fixture uses two 60-watt candelabra bulbs *(included)*
- 4.5" downrod included
- Five Reversible Blades
- Ships to Canada



SW405
Remote Control with
Built-in Receiver

Amhurst Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
5422	67	80

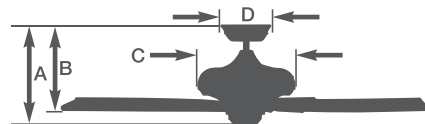

A: 15.1" B: 11.8" C: 9.1" D: 6.3"