



Builder - CF700


- CF700BS** - Brushed Steel Housing, Dark Cherry/Mahogany Blades
- CF700RB** - Oil Rubbed Bronze Housing, Dark Cherry/Medium Oak Blades
- CF700WW** - Appliance White Housing, Appliance White/Bleached Oak Blades

- 52" blade span
- Die-cast hanger ball and bracket
- Light fixture adaptable
- 4.5" downrod included
- Five Reversible Blades
- Energy Star Rated
- Ships to Canada



Builder Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
5241	64	80

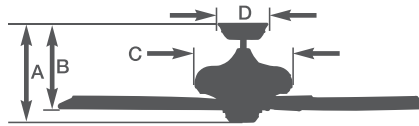

A: 12.0" B: 11.0" C: 11.5" D: 5.1"

go **ABOVE**[™]