



Style Category:
Contemporary

Motor: 153x18mm

Blade Pitch: 12°

RPM Range: 75-195

High Speed Amps: 0.5

Accepts 2.5" Downrod:
No

Wet/Damp: Wet*

Control Included:
6-Speed Remote Control

Receiver Included:
RC188

Remote Reverse Switch

Dimming Light: Yes

AL100 Adaptable: No

52" Curva Sky™ - CF152

NEW FINISH ADDITION - GRAPHITE

CF152GRT - Graphite with Weather-Resistant Graphite Blades, Opal Matte Glass
- **DEALER PRICE: \$166.11 | IMAP: \$299.00**

CF152BS - Brushed Steel, Weather-Resistant Brushed Steel Blades, Opal Matte Glass
- **DEALER PRICE: \$166.11 | IMAP: \$299.00**

CF152ORB - Oil Rubbed Bronze, Weather-Resistant Oil Rubbed Bronze Blades, Opal Matte Glass
- **DEALER PRICE: \$166.11 | IMAP: \$299.00**

CF152WW - Appliance White, Weather-Resistant Appliance White Blades, Opal Matte Glass
- **DEALER PRICE: \$155.00 | IMAP: \$279.00**


- 52" Blade Span
- Integrated Light Fixture Uses Two 50-Watt Mini-Candelabra Halogen Bulbs (Included)
- Three Weather-Resistant Blades
- Removable No-Light Plate Included
- 6-Speed L.E.D. Remote Control
- Wet Location (*Brushed Steel Not Recommended for Outdoor Use)
- Ships to Canada
- Also Available in 44" Span as CF144



*Brushed Steel not recommended for outdoor use

52" Curva Sky™ Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
5393	46	116

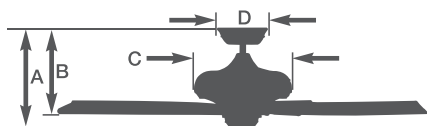

A: 12.6" B: 12.0" C: 9.6" D: 6.5"

Included:



THREE WEATHER-RESISTANT BLADES



REMOVABLE NO-LIGHT PLATE



INTEGRATED LIGHT FIXTURE



6-Speed Remote Control with Receiver*

*Controls are recommended for indoor use only.