



Style Category:
Transitional

Motor: 153x17mm

Blade Pitch: 12°

RPM Range: 68-155

High Speed Amps: 0.4

Accepts 2.5" Downrod:
Yes

Wet/Damp: Indoor

Control Included:
4-Speed Slide Control

Receiver Included:
N/A

Manual Reverse Switch

Dimming Light: N/A

AL100 Adaptable: No

Keane - CF320


NEW FINISH ADDITION - GRAPHITE

- CF320RGRT** - Graphite with Charcoal/Timber Gray Blades *NEW BLADE FINISH* - Dealer Price: \$88.33 | IMAP: \$159.00
- CF320SGRT** - Graphite with Brushed Steel/Barbeque Black Blades - Dealer Price: \$88.33 | IMAP: \$159.00
- CF320CGRT** - Graphite with Natural Cherry/Walnut Blades - Dealer Price: \$88.33 | IMAP: \$159.00
- CF320WGRGRT** - Graphite with Satin White/Maple Blades - Dealer Price: \$88.33 | IMAP: \$159.00
- CF320SBS** - Brushed Steel with Brushed Steel/Barbeque Black Blades - Dealer Price: \$88.33 | IMAP: \$159.00
- CF320CBS** - Brushed Steel with Natural Cherry/Walnut Blades - Dealer Price: \$88.33 | IMAP: \$159.00
- CF320WBS** - Brushed Steel with Satin White/Maple Blades - Dealer Price: \$88.33 | IMAP: \$159.00
- CF320RBS** - Brushed Steel with Charcoal/Timber Gray Blades *NEW BLADE FINISH* - Dealer Price: \$88.33 | IMAP: \$159.00
- CF320WSW** - Satin White with Satin White/Maple Blades - Dealer Price: \$82.78 | IMAP: \$149.00
- CF320CSW** - Satin White with Natural Cherry/Walnut Blades - Dealer Price: \$82.78 | IMAP: \$149.00
- CF320SSW** - Satin White with Brushed Steel/Barbeque Black Blades - Dealer Price: \$82.78 | IMAP: \$149.00
- CF320RSW** - Satin White with Charcoal/Timber Gray Blades *NEW BLADE FINISH* - Dealer Price: \$82.78 | IMAP: \$149.00

- 52" Blade Span
- 3 Reversible Blades
- 4.5" Downrod Included





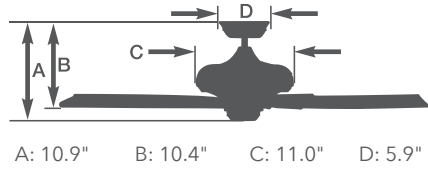



Keane Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
5069	49.4	103.6

Included:



**THREE
REVERSIBLE
BLADES**



4-Speed
Slide Fan
Control