



**NEW!**

Style Category: Contemporary  
 Motor: EcoMotor  
 Blade Pitch: 14°  
 RPM Range: Not Available  
 High Speed Amps: Not Available  
 Accepts 2.5" Downrod: Yes  
 Wet/Damp: Indoor  
 Control Included: 6-Speed Wall Control  
 Receiver Included: RC188  
 Manual Reverse Switch  
 Dimming Light: No  
 AL100 Adaptable: No


## Ideal - CF330

**CF330BQ** - Barbeque Black with Polished Nickel Accents and Barbeque Black Blades  
 - Dealer Price: \$229.50 | IMAP: \$459.00

**CF330SW** - Satin White with Polished Nickel Accents and Satin White Blades - Dealer Price: \$229.50 | IMAP: \$459.00

**CF330GRT** - Graphite with Brushed Steel Accents and Graphite Blades - Dealer Price: \$229.50 | IMAP: \$459.00

- 54" Blade Span
- Integrated L.E.D. Light Fixture
  - 2,200 Lumens
  - 95 CRI
  - 3,000 CCT
  - 20 Watts
- 4.5" Downrod Included

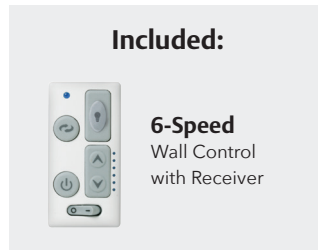

  
**ECOMOTOR®**


 **INTEGRATED LED LIGHTING**

 **LIMITED LIFETIME MOTOR WARRANTY**

 **SHIPS TO CANADA**

### Ideal Energy Ratings at High Speed

Energy efficiency information was not available at the time of publication. Visit [emersonfans.com](http://emersonfans.com) for up-to-date information.

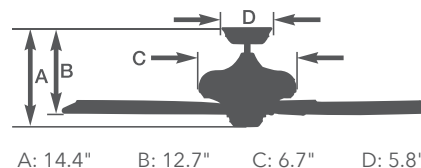

**go ABOVE®**

Specifications subject to change without notice.