



Style Category:  
Indoor/Outdoor  
Motor: 172x20mm  
Blade Pitch: 12.5°  
RPM Range:  
Not Available  
High Speed Amps:  
Not Available  
Accepts 2.5" Downrod:  
No  
Wet/Damp: Wet  
Control Included:  
4-Speed Wall Control  
Receiver Included:  
RCFP  
Manual Reverse Switch  
Dimming Light: No  
AL100 Adaptable: No

**NEW!**


## Rockpointe - CF630

**CF630VS** - Vintage Steel with Weather-Resistant Walnut Blades - **Dealer Price: \$266.11 | IMAP: \$479.00**

**CF630ORB** - Oil Rubbed Bronze with Weather-Resistant Walnut Blades - **Dealer Price: \$266.11 | IMAP: \$479.00**

**CF630SW** - Satin White with Weather-Resistant Driftwood Blades - **Dealer Price: \$249.44 | IMAP: \$449.00**

- 54" Blade Span
- Integrated Light Fixture Uses Three 13-Watt CFL E26 Bulbs *(included)*
- 4.5" Downrod Included

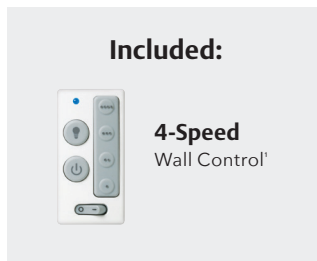


**WET LOCATION RATED**

**INTEGRATED LIGHTING**

**LIMITED LIFETIME MOTOR WARRANTY**

### Rockpointe Energy Ratings at High Speed

Energy efficiency information was not available at the time of publication. Visit [emersonfans.com](http://emersonfans.com) for up-to-date information.

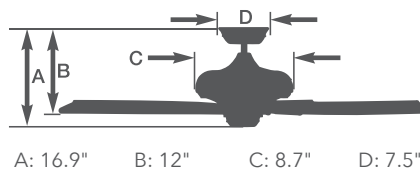

**go ABOVE®**

Specifications subject to change without notice.