



Style Category: Transitional  
 Motor: EcoMotor  
 Blade Pitch: 16°  
 RPM Range: 50-150  
 High Speed Amps: 0.38  
 Accepts 2.5" Downrod: No  
 Wet/Damp: Damp  
 Control Included: 6-Speed Wall Control  
 Receiver Included: EcoMotor Receiver  
 Remote Reverse Switch  
 Dimming Light: N/A  
 AL100 Adaptable: No

## Carrera Grande® Eco - CF788


### NEW FINISH ADDITIONS

- CF788VS** - Vintage Steel Housing - **DEALER PRICE: \$215.50 | IMAP: \$431.00**
- CF788BS** - Brushed Steel Housing - **DEALER PRICE: \$215.50 | IMAP: \$431.00**
- CF788AP** - Antique Pewter Housing - **DEALER PRICE: \$215.50 | IMAP: \$431.00**
- CF788GES** - Golden Espresso Housing - **DEALER PRICE: \$215.50 | IMAP: \$431.00**
- CF788GBZ** - Gilded Bronze Housing - **DEALER PRICE: \$215.50 | IMAP: \$431.00**
- CF788ORB** - Oil Rubbed Bronze Housing - **DEALER PRICE: \$215.50 | IMAP: \$431.00**
- CF788VNB** - Venetian Bronze Housing - **DEALER PRICE: \$215.50 | IMAP: \$431.00**
- CF788SW** - Satin White Housing - **DEALER PRICE: \$205.50 | IMAP: \$411.00**

- 44", 54", 60" or 72" Blade Span
- Light Fixture Adaptable
- 4.5" Downrod Included
- Blade Select Series Blades (Sold Separately)
- Damp Location  
(\*Antique Pewter & Brushed Steel Not Recommended for Outdoor Use)
- Energy Star Rated
- EcoMotor
- Ships to Canada

### Carrera Grande® Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
7929	29	265

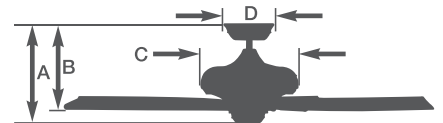

A: 14.5" B: 13.0" C: 13.4" D: 7.1"

**BLADE SELECT**  
SERIES

**ECOMOTOR**

**ENERGY STAR**

**DAMP LOCATION**  
RATED

**SHIPS TO CANADA**  
FAN ONLY

**L.E.D. LIGHT**  
FIXTURE ADAPTABLE

**LIMITED LIFETIME**  
MOTOR WARRANTY

### Included:



**6-Speed**  
Wall Control  
with Receiver\*

\* Controls are recommended for indoor use only.

1 Energy Star testing completed with B78 blade series.  
 2 Antique Pewter & Brushed Steel not recommended for outdoor use.

go **ABOVE**

Specifications subject to change without notice.