



44" Curva Sky™ - CF144

- CF144BS** - Brushed Steel Housing, Weather-Resistant Brushed Steel Blades, Opal Matte Glass
- CF144WW** - Appliance White Housing, Weather-Resistant Appliance White Blades, Opal Matte Glass
- CF144ORB** - Oil Rubbed Bronze Housing, Weather-Resistant Appliance Blades, Opal Matte Glass


- 44" blade span
- Integrated light fixture uses two 50-watt mini-candelabra halogen bulbs *(included)*
- Three Weather-Resistant Blades
- Removable No-Light Plate Included
- 6-Speed LED Remote Control
- Wet Location (in WW and ORB Finishes Only)
- Ships to Canada
- Also Available in 52" Span as CF152



Remote Control with Receiver

44" Curva Sky™ Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
4217	45	93

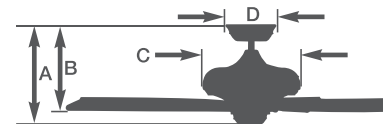

A: 12.6" B: 12.0" C: 9.6" D: 6.5"

go **ABOVE™**