



Luxe Eco™ - CF550

CF550DMBS- Brushed Steel Housing, Dark Mahogany Blades & Opal Matte Glass

CF550WABS- Brushed Steel Housing, Walnut Blades & Opal Matte Glass

CF550DMORB - Oil Rubbed Bronze Housing, Dark Mahogany Blades & Opal Matte Glass

CF550WAORB - Oil Rubbed Bronze Housing, Walnut Blades & Opal Matte Glass


- 54" blade span
- Integrated light fixture uses two 50-watt mini-candelabra halogen bulbs *(included)*
- 4.5" downrod included
- Five custom wood blades
- Removable No-Light Plate included
- 6-speed wall control with receiver
- EcoMotor
- Ships to Canada



6-Speed Wall Control
with Receiver

Luxe Eco™ Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
6974	33	210

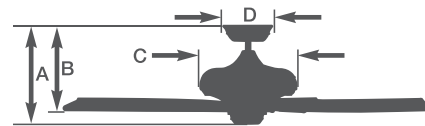

A: 15.8" B: 12.0" C: 9.6" D: 6.4"

go **ABOVE**™