



42" Pro Series II - CF710

- CF710BS** - Brushed Steel Housing, Dark Cherry, Mahogany Blades, Opal Matte Glass
- CF710WW** - Appliance White Housing, Appliance White/Bleached Oak Blades, Opal Matte Glass
- CF710ORB** - Oil Rubbed Bronzed Housing, Dark Cherry/Medium Oak Blades, Opal Matte Glass

- 42" blade span
- Slip-on mounting bracket
- Snap-on glass for easy installation
- Light fixture furnished with three 13-watt medium base compact fluorescent bulbs *(included)*
- UL rated for four 60-watt incandescent
- Precision-Lock™ blade arms with pre-attached screws allow for quick and easy assembly of blades
- Removable light fixture can be replaced with switch cover if desired *(included)*
- Easy install mounting bracket
- Dual mounting for close-to-the-ceiling or downrod installation
- 3.5" downrod included
- Removable No-Light Plate included
- Five Reversible Blades




**LIMITED LIFETIME
MOTOR WARRANTY**



**QUICK & EASY
INSTALLATION**

42" Pro Series II Energy Ratings at High Speed

Airflow Cubic Ft Per Min.	Electricity Use Watts (Excl. Lights)	Airflow Efficiency Cubic Ft Per Min. Per Watt
3834	45	86

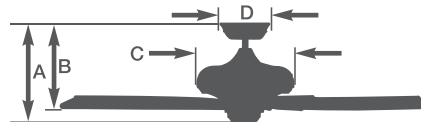

A: 14.5"/17.3" B: 8.3"/11.0" C: 11.5" D: 5.2"

go **ABOVE**™