



Southtowne - CF4900

- CF4900BS** - Brushed Steel Housing, Dark Mahogany/Walnut Blades, Opal Matte Glass
- CF4900ORB** - Oil Rubbed Bronze Housing, Chocolate/Walnut Blades, Opal Matte Glass
- CF4900VS** - Vintage Steel Housing, Riverwash/Walnut Blades, Opal Matte Glass


- 54" blade span
- Integrated light fixture uses two 50-watt halogen bulbs (*included*)
- 4.5" downrod included
- Five Blades
- Ships to Canada (for Spring availability)



6 Speed Wall Control
with Receiver

Southtowne Energy Ratings at High Speed

| Airflow Cubic Ft Per Min. | Electricity Use Watts (Excl. Lights) | Airflow Efficiency Cubic Ft Per Min. Per Watt |
|------------------------------|---|--|
| 5556 | 97 | 57 |

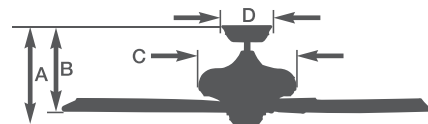

A: 15" B: 10.3" C: 11.9" D: 6.3"

go **ABOVE**™

Specifications subject to change without notice.